

Reshape The New Infrastructure of Tomorrow

Panduit's relentless pursuit of innovation has solidified its reputation as a provider of one-stop network infrastructure solutions. By incorporating cutting-edge technologies, Panduit empowers businesses to adapt seamlessly to change, ensuring robust and scalable solutions. This holistic approach keeps businesses competitive, resilient, and ready for the future in an ever-evolving IT landscape.

SMART CABINET SOLUTION

SMART CABINET- VERTICAL PDU



CABINET:
DAE6222B
DAE8222BF

PDU:
E30B06M
E42B11M
E24D03M
E36D01M
E24G11M
E24G06M

OPTIONAL ACCESSORIES:
ENV01



OPTIONAL ACCESSORIES:
ENV01

**1 SET INCLUDES 1 CABINET AND 2 PDU.

SMART CABINET - HORIZONTAL PDU



CABINET:
DAE6222B
DAE8222BF

PDU:
E12B01M
E08D01M


**1 SET INCLUDES 1 CABINET AND 2 PDU.

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
DAE6222B	Net-Verse™ D-Type Cabinet Frame, 42 RU. Top panel with brush openings. Two sets cage nut equipment rails. Single hinge perforated front door. Split perforated rear doors. Horizontally split side panels (4). Two full length PDU brackets. Dimensions: 2045mm x 600mm x 1200mm. Colour: Black	1	1
DAE8222BF	Net-Verse™ D-Type Cabinet Frame, 42 RU. Top panel with brush openings. Two sets cage nut equipment rails. Single hinge perforated front door. Split perforated rear doors. Horizontally split side panels (4). Two full length PDU brackets. Includes cable management fingers. Dimensions: 2045mm x 600mm x 1200mm. Colour: Black	1	1
ENV01	Humidity and Temperature sensor	1	1

Part Number	Form Factor	Input Current per Phase	Input Phase	Input Plug Type	Outlet Count	Outlet Type	Output Voltage
Basic Power Distribution Units (PDUs)							
E30B06M	0U Mid	32	1	IEC60309	30	(24)C13, (6)C19	240
E42B11M	0U Full	32	3	IEC60309	42	(30)C13, (12)C19	240
E12B01M	1U Horizontal	16	1	IEC60309	12	(12)C13	240
Monitored Input Intelligent PDU							
E24D03M	0U Full	32	1	IEC60309	24	(20)C13, (4)C19	240
E36D01M	0U Full	32	3	IEC60309	42	(30)C13, (12)C19	240
E08D01M	1U Horizontal	16	1	IEC60309	8	(8)C13	240
Monitored and Switched per Outlet Intelligent PDU							
E24G11M	0U Full	32	1	IEC60309	24	(20)C13, (4)C19	240
E24G06M	0U Full	32	3	IEC60309	36	(24)C13, (12)C19	240

Contact Panduit Customer Service for different combination and other types of PDU's and environmental monitoring options.

WIRE BASKET OVERHEAD CABLE TRAY ROUTING SYSTEM

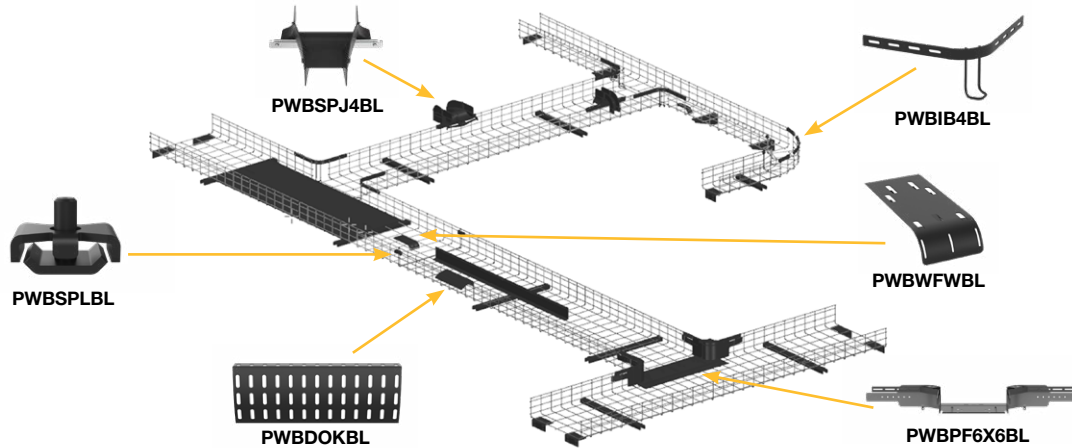


Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
PWB4X12BL	4" (102mm) height x 12" (305mm) wide x 10 ft. (3 metre) black powdered coated long pathway section used to carry cables horizontally throughout the system.	10	—
PWBIB4BL	Wire Basket 4 in. (102mm) radius intersection 90° bracket to make right-angle, tee-angle and fourway cross intersection.	1	—
PWBHKBL	Wire Basket Hardware Kit for radius intersection 90° bracket, Black,	50	—
PWBSP4BL	Bolted-style electrozinc splice connector quickly joins Wire Basket Pathways at all intersections.	50	—
PWBDOCKBL	12" black powdered coated drop out kit for cables transitioning down into the racks or cabinets from within the Wire Basket Pathway.	1	—
PWBWFWBL	Tool-less Black wide waterfall for cables transitioning down into the racks or cabinets from the side of the Wire Basket Pathway.	1	—
PWBTB12BL	Bracket used to support 12 in. (305mm) wide Wire Basket Pathway from the ceiling using a pair of 1/2" or 12mm threaded rod drops.	1	—
PWBSCBL	Struts clip installed on unistrut bracket used to support 12 in. (305mm) wide Wire Basket Pathway from the ceiling using a pair of 1/2" or 12mm threaded rod drops.	1	—

Contact Panduit Customer Service for **additional widths availability** - 4" (100mm), 6" (150mm), 8" (203mm), 18" (457mm) and 24" (610mm) or **additional height availability** - 2" (50mm), 4" (100mm) and 6" (150mm). In addition, Wire Basket is available in Electrozinc Option.

Contact Panduit Customer Service for additional information or, www.panduit.com. For pathway, order number of feet required, in multiples of standard 10' length increments.

SHIELDED COPPER CABLING SYSTEM

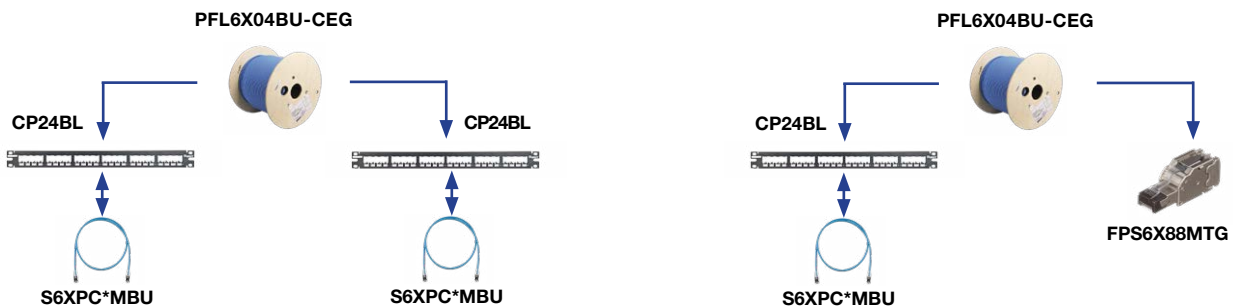

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
PFL6X04BU-CEG	Category 6A F/UTP cable, 23 AWG, Blue, LSZH, 305m.	Reel	18
CJS6X88TGBUY	Category 6A RJ45 shielded Mini-Com™ Jack, Black.	1	50
CP24BL	24-port all-metal shielded patch panel.	1	10
FPS6X88MTG	Category 6A shielded field term RJ45 plug.	1	50
S6XPC*MBU	Category 6A, S/FTP patch cord, 26 AWG, Blue.	1	10
S6PC*MBU	Category 6, S/FTP patch cord, 26 AWG, Blue	10	50
EGJT-1	TG Jack and Field Term Plug termination tool, Green.	1	-

* Available metres: 1, 2, 3, 5 or 10 metres. Contact Panduit Customer Service for more information.